



Every lab, every day

Explore a portfolio of high-quality lab essentials

Freezers and refrigerators

Product description	Cat. No.
Thermo Scientific™ TSX Series ultra-low temperature freezers	
400-box capacity, 115V, 60 Hz	TSX40086A
400-box capacity, 208–230V, 60 Hz	TSX40086D
500-box capacity, 115V, 60 Hz	TSX50086A
500-box capacity, 208–230V, 60 Hz	TSX50086D
600-box capacity, 115V, 60 Hz	TSX60086A
600-box capacity, 208–230V, 60 Hz	TSX60086D
700-box capacity, 115V, 60 Hz	TSX70086A
700-box capacity, 208–230V, 60 Hz	TSX70086D
Thermo Scientific™ TDE Series ultra-low temperature freezers	
400-box capacity, 115V, 60 Hz	TDE40086FA
400-box capacity, 208–230V, 60 Hz	TDE40086FD
500-box capacity, 115V, 60 Hz	TDE50086FA
500-box capacity, 208–230V, 60 Hz	TDE50086FD
600-box capacity, 115V, 60 Hz	TDE60086FA
600-box capacity, 208–230V, 60 Hz	TDE60086FD
Thermo Scientific™ TSX Series high-performance freezers and refrigerators	
Solid door, –30°C auto defrost, 23 cu. ft., 115V, 60 Hz	-
Solid door, –20°C auto defrost, 23 cu. ft., 115V, 60 Hz	TSX2320FA
Glass door, 23 cu. ft., 115V, 60 Hz	TSX2305GA
Solid door, 23 cu. ft., 115V, 60 Hz	TSX2305SA
Undercounter design, single glass door, 5.5 cu. ft., 100–240V, 50–60 Hz	TSX505GA
Undercounter design, single solid door, 5.5 cu. ft., 100–240V, 50–60 Hz	TSX505SA



Thermo Scientific™ Sorvall™ Legend™ microcentrifuges and small bench centrifuges

Product description	Cat. No.
Micro 17 Microcentrifuge, 120V, 60 Hz	75002431
Micro 21 Microcentrifuge, 120V, 60 Hz	75002436
Micro 17R Microcentrifuge, 120V, 60 Hz	75002441
Micro 21R Microcentrifuge, 120V, 60 Hz	75002446



Thermo Scientific™ Savant™ SpeedVac™ vacuum concentrator system

Product description	Cat. No.
DNA 130 Integrated Vacuum Concentrator System	13875331

Thermo Scientific™ F1-ClipTip™ variable volume single channel pipettes

Product description	Cat. No.
1–10 µL	04100513
2–20 µL	14488014N
5–50 µL	14488015N
10–100 µL	14488016N
30–300 µL	14488018N



Thermo Scientific™ Sorvall™ WX+ Ultracentrifuge Series

Product description	Cat. No.
100+ Ultracentrifuge, 100,000 rpm	75000100
90+ Ultracentrifuge, 90,000 rpm	75000090
80+ Ultracentrifuge, 80,000 rpm	75000080

Thermo Scientific™ rockers, rotators, shakers, and mixers

Product description	Cat. No.
Digital Platform Rockers	88882013
Digital Tube Rockers	88882017
Digital Mini Rotators	88882007
Digital Microplate Shakers	88882005
Tube Revolver Rotator	88881001
Digital Waving Rotators	88882003
Digital Vortex Mixers	88882009
Basic Vortex Mixers	88882011



Thermo Scientific™ thermal mixers with blocks

Product description	Cat. No.
Thermal Mixer with Blocks	13687711
Block, 24 x 2.0 mL microtubes	13687713
Block, 24 x 1.5 mL microtubes	13687712
Block, 20 x 0.5 mL microtubes and 12 x 1.5 mL microtubes	13687714
Block, 20 x 0.2 mL microtubes and 12 x 1.5 mL microtubes	13687715
Mixer with 24 x 1.5 mL microtube block	13687717
Block, 96-well microplates/tube strips (0.2 mL)	13687716
Mixer with 24 x 2 mL microtube block	13687718
Mixer with 20 x 0.2 mL and 12 x 1.5 mL microtube block	13687719
Mixer with 96-well microplates/tube strips, 0.2 mL block	13687720
Mixer with 20 x 0.5 mL and 12 x 1.5 mL microtube block	13687721



Thermo Scientific™ Solaris™ open air orbital shakers

Product description	Cat. No.
Small Open Air Orbital Shaker, 25 kg	-
Large Open Air Orbital Shaker, 43 kg	-



Storage plates and microplates

Product description	Cat. No.
Thermo Scientific™ Nunc™ 96-Well Polypropylene DeepWell™ Storage Plates	
Natural, round bottom, sterile, barcode	12565395
Natural, round bottom, non-sterile, barcode	12565394
Natural, U-shape bottom, non-sterile, barcode, 2,000 µL	12565606
Thermo Scientific™ Nunc™ 96-Well Polypropylene Storage Microplates	
Natural, V-bottom, non-sterile, barcode, 2,000 µL	12565650
Natural, V-bottom, non-sterile, 450 µL	12565436
Natural, U-shape bottom, non-sterile, 450 µL	12565368



Thermo Scientific™ TSV Value convertible freezers/refrigerators

Product description	Cat. No.
400-box capacity, 115V, 60 Hz	TSX40086A
400-box capacity, 208–230V, 60 Hz	TSX40086D
500-box capacity, 115V, 60 Hz	TSX50086A
500-box capacity, 208–230V, 60 Hz	TSX50086D
600-box capacity, 115V, 60 Hz	TSX60086A
600-box capacity, 208–230V, 60 Hz	TSX60086D
700-box capacity, 115V, 60 Hz	TSX70086A
700-box capacity, 208–230V, 60 Hz	TSX70086D
400-box capacity, 115V, 60 Hz	01257916
400-box capacity, 208–230V, 60 Hz	01257917
500-box capacity, 208–230V, 60 Hz	01257925
600-box capacity, 115V, 60 Hz	01257932
600-box capacity, 208–230V, 60 Hz	01257933
Solid door, –30°C auto defrost, 23 cu. ft., 115V, 60 Hz	TSX2330FA
Solid door, –20°C auto defrost, 23 cu. ft., 115V, 60 Hz	TSX2320FA
Glass door, 23 cu. ft., 115V, 60 Hz	TSX2305GA
Solid door, 23 cu. ft., 115V, 60 Hz	TSX2305SA
Undercounter design, single glass door, 5.5 cu. ft., 100–240V, 50–60 Hz	TSX505GA
Undercounter design, single solid door, 5.5 cu. ft., 100–240V, 50–60 Hz	TSX505SA



Thermo Scientific™ XBF40D blast freezers

Product description	Cat. No.
XBF40D –40°C Blast Freezer	13990410
XBF40D-MD –40°C Blast Freezer for Plasma	13990411

Thermo Scientific™ screw top microcentrifuge tubes

Product description	Cat. No.
Screw Cap Micro Tubes, 2 mL, natural, sterile	21403201
Screw Cap Micro Tubes, 1.5 mL, natural, sterile	14755287




Thermo Scientific™ snap cap low retention microcentrifuge tubes

Product description	Cat. No.
Snap Cap Low Retention Microcentrifuge Tube, 1.5 mL, natural, non-sterile	21402902
Snap Cap Low Retention Microcentrifuge Tube, 2.0 mL, natural, sterile	21402904



Pipettes, tips, and racks

Product description	Cat. No.
Thermo Scientific™ SoftFit-L™ pipette tips, 20 µL	
Filtered, Sterile, Hinged Rack	21402550
Non-Filtered, Sterile, Hinged Rack	21402552
Non-Filtered, Non-sterile, Hinged Rack	21402554
Filtered, Low Retention, Hinged Rack	21402551
Non-Filtered, Low Retention, Sterile, Hinged Rack	21402553
Non-Filtered, Non-sterile, Hinged Rack	21402555
SoftFit-L pipette tips, 200 µL	
Filtered, Sterile, Hinged Rack	21402561
Non-Filtered, Sterile, Hinged Rack	21402563
Non-Filtered, Non-sterile, Hinged Rack	21402565
Filtered, Sterile, Hinged Rack	21402562
Non-Filtered, Sterile, Hinged Rack	21402564
Non-Filtered, Non-sterile, Hinged Rack	21402566
SoftFit-L pipette tips, 300 µL	
Filtered, Sterile, Hinged Rack	21402571
Non-Filtered, Sterile, Hinged Rack	21402573
Non-Filtered, Non-sterile, Hinged Rack	21402575
Filtered, Sterile, Hinged Rack	21402572
Non-Filtered, Sterile, Hinged Rack	21402574
Non-Filtered, Non-sterile, Hinged Rack	21402576
SoftFit-L pipette tips, 1,000 µL	
Filtered, Sterile, Hinged Rack	21402581
Non-Filtered, Sterile, Hinged Rack	21402583
Non-Filtered, Non-sterile, Hinged Rack	21402585
Filtered, Sterile, Hinged Rack	21402582
Non-Filtered, Sterile, Hinged Rack	21402584
Non-Filtered, Non-sterile, Hinged Rack	21402586
SoftFit-L pipette tips, 1,200 µL	
Filtered, Sterile, Hinged Rack	21402592
Non-Filtered, Sterile, Hinged Rack	21402594
Non-Filtered, Non-sterile, Hinged Rack	21402596
Filtered, Sterile, Hinged Rack	21402593
Thermo Scientific™ Finnpiquette™ F1 variable volume pipettes	
1–10 µL	14386302N
2–20 µL	14386305N
10–100 µL	14386306N
20–200 µL	14386307N
100–1,000 µL	14386309N
Thermo Scientific™ Finnpiquette™ F1 multichannel pipettes	
1–10 µL	14386349N
10–100 µL	14386351N
30–300 µL	14386352N

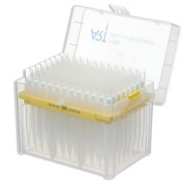

Thermo Scientific™ ART™ pipette tips

Barrier Specialty Pipette Tips	14386300N
Barrier Extended Length Pipette Tips	14386302N
Barrier Pipette Tips in Hinged Racks, 10 µL	14386306N
Barrier Pipette Tips in Hinged Racks, 20 µL	14386352N
Barrier Pipette Tips in Hinged Racks, 100 µL	14386351N
Barrier Pipette Tips in Hinged Racks, 200 µL	14386305N
Non-Filtered Standard Hinged Rack Pipette Tips	13811103

Thermo Scientific™ FinnpiPET™ Stand

F-Stand, Linear Stand, white	14245160
------------------------------	----------

Thermo Scientific™ automated plate heat sealers

Product description	Cat. No.
ALPS 3000 Automated Microplate Heat Sealer	AB3000
ALPS5000 Automated Plate Heat Sealer	AB5000

**Thermo Scientific™ biological safety cabinet packages**

Product description	Cat. No.
120V, 50/60 Hz, 100 cm W	13261334
120V, 50/60 Hz, 160 cm W	13261338
120V, 50/60 Hz, 130 cm W	13100752PM
120V, 50/60 Hz, 190 cm W	13100753PM

Incubators

Product description	Cat. No.
Thermo Scientific™ Heratherm™ incubators	
Compact Microbiological Incubator	50125590H
Advanced Protocol Microbiological Incubator	51028068H
Advanced Protocol Security Microbiological Incubator, 104 L	51028070H
General Protocol Microbiological Incubator, 230V, 405 L	51029322H
Advanced Protocol Security Microbiological Incubator, 720 L	51029336H
Refrigerated Incubator	51031562H
General Protocol Microbiological Incubator, 120V, 117 L	51028064H

Thermo Scientific™ Forma™ environmental chambers

Environmental Chamber Model 3920, 821.2 L, Stainless Steel	13262340
Environmental Chamber Model 3940, 821.2 L, Stainless Steel	13067066

Thermo Scientific™ Heracell™ VIOS 160i CO₂ Incubator

165 L, Copper, 120V	13998254
---------------------	----------



Thermo Scientific™ Heratherm™ ovens

Product description	Cat. No.
General Protocol Ovens, 105 L, Gravity Convection	51028872H
General Protocol Ovens, 104 L, Mechanical Convection	51028873H
Advanced Protocol Security Ovens	51028127H
Advanced Protocol Ovens, 208–240VAC, 60 Hz	51029330H



Furnaces

Product description	Cat. No.
Thermo Scientific™ Thermolyne™ furnaces	
Benchtop 1,100°C Muffle Furnaces	105521
Premium Large Muffle Furnaces	10557EPM
Thermo Scientific™ Lindberg/Blue M™ furnaces	
Moldatherm™ Box Furnaces	10549165
LGO Box Furnaces	10549142

Thermo Scientific™ Matrix™ storage tubes

Product description	Cat. No.
V-bottom 1.0 mL screw top tubes, 5 racks of 96/case, colorless	14754558
V-bottom 1.0 mL screw top tubes, 5 racks of 96/case	14754563
1.0 mL barcoded screw top tubes, 5 racks of 96/case	14754574
0.5 mL ScrewTop Tubes in Barcoded Latch Racks	14754598
0.5 mL ScrewTop Tri-coded Tubes	14754610
1.0 mL ScrewTop Tri-coded Tubes	14754556
Screw top tube cap tray, case of 480, colorless	14754667
Screw top tube cap tray, case of 480, purple	14754682



[Check out](#) our full selection of Matrix storage tubes.

Find out more at fisherhealthcare.com

Distributed by Fisher Scientific. Contact us today:

In the United States

Order online: fishersci.com

Call customer service: 1-800-766-7000

For General Laboratory Use. © 2022 Thermo Fisher Scientific Inc. All rights reserved. All trademarks are the property of Thermo Fisher Scientific and its subsidiaries unless otherwise specified.

COL023704 JSA 05/23 BN224997855-US

 **fisher**
healthcare
part of Thermo Fisher Scientific