

Entry-Level Stereo Microscopes

Basic, fixed magnifications stereo microscope; perfect for the simple jobs

Unique Features:

VIEWING HEAD

- Binocular viewing head with 45° angle
- Interpupillary adjustment 55mm to 75mm
- Diopter adjustment

PRESETS

- Transmitted only
- Reflected only
- Discopic only
- Darkfield only
- Reflected and Transmitted
- All on (DF, DI, REFL, TRANS)

FOCUSING

- 70mm working distance
- 40mm height adjustment
- Coarse focus adjustment

OPTICAL SYSTEM

- Superior Optical Clarity
- 10X WF eyepieces
- Dual magnification
- 1X/3X or 2X/4X

ILLUMINATION

- LED ring in transmitted light provides homogeneous light distribution
- LED incident illumination
- Eco-friendly and energy-efficient LED system
- Membrane switch controls
- LED light indicator on membrane switch identifies which lighting technique is turned on

STAND

- Low-profile, plain stage with clips
- Plain stand designed to accommodate larger samples
- Compact design



Specifications


Hardware	Descriptions
Viewing Head	Binocular Viewing Head, Inclined at 45°. Interpupillary Distance 55mm - 75mm
Eyepiece	WF 10X
Zoom Objective	2X, 4X (03-000-038) 1X, 3X (03-000-037)
Focusing System	Coarse Adjustment Range 40mm
Working Distance	Working Distance 57mm
Stage	Frosted, Glass/Black & White Stage Plate
Illumination	LED Incident Illumination LED Transmitted Illumination
Dimensions	W 15.4 x D 20.3 x H 24.2cm

Magnification Chart

Model	Magnification
10X eyepiece with 1X/3X	10X, 30X
10X eyepiece with 2X/4X	20X, 40X

Ordering Information

Product	Cat. No.
45° Inclined Binocular Head, Interpupillary Range 55mm - 75mm, Coarse Focus, 1X/3X objective, Low Profile LED Stand, Transmitted/Reflected, 10X eyepieces	03-000-037
45° Inclined Binocular Head, Interpupillary Range 55mm - 75mm, Coarse Focus, 2X/4X, 1X/3X objective, Low Profile LED Stand, Transmitted/Reflected, Rechargeable, 10X eyepieces	03-000-038

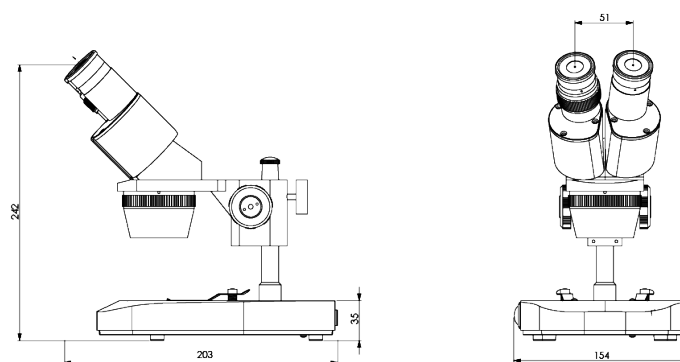

Measurements are in mm, overall dimension may change slightly depending on model

Find out more at fishersci.com

In the United States:

For customer service, call 1-800-766-7000
To fax an order, use 1-800-926-1166
To order online: fishersci.com

In Canada:

For customer service, call 1-800-234-7437
To fax an order, use 1-800-463-2996
To order online: fishersci.ca



© 2018 Thermo Fisher Scientific Inc. All rights reserved.
Trademarks used are owned as indicated at fishersci.com/trademarks.

BN20191623