

A 3D molecular model featuring a network of blue spheres connected by thin blue rods. A central cluster of orange spheres is highlighted with a bright light flare. The background is a light blue gradient with faint, out-of-focus molecular structures.

thermo scientific

Chemicals

# New molecules

for life science research

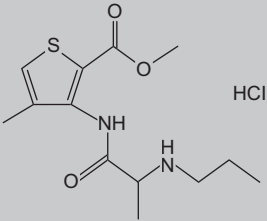
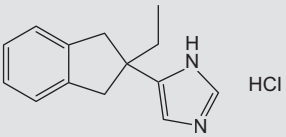
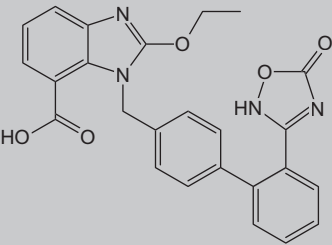
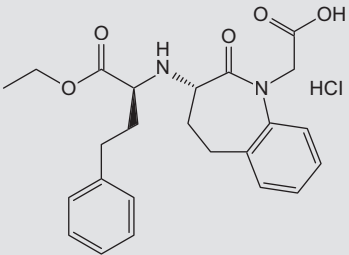
Find it at [fishersci.com](https://fishersci.com) and [fishersci.ca](https://fishersci.ca)

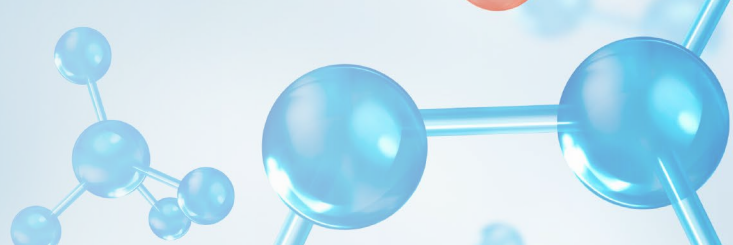
 **fisher scientific**  
part of Thermo Fisher Scientific

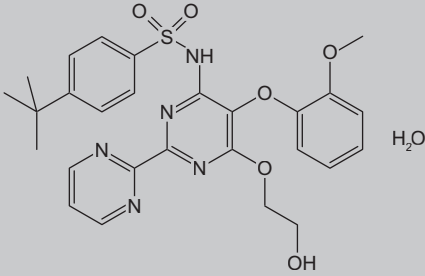
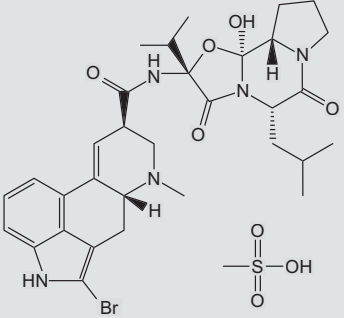
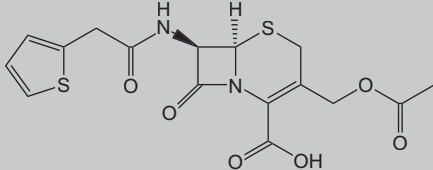
 
# New molecules for life science research

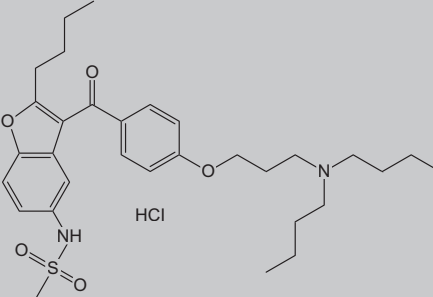
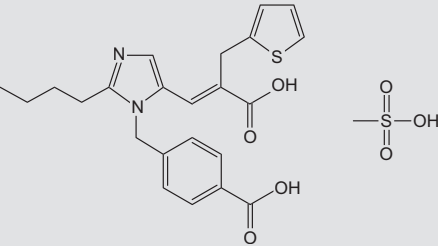
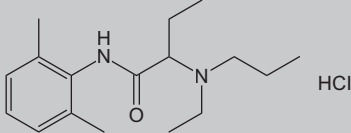
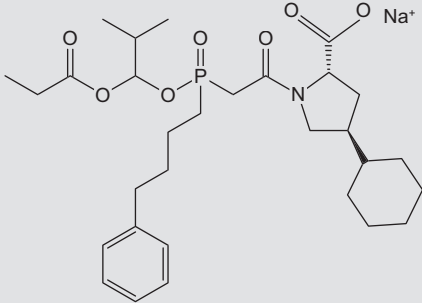
We are regularly introducing new products into our portfolio. Discover the latest bioactive molecules for life science (for research use only) now available from the Thermo Scientific brand.

## New bioactive molecules available from the Thermo Scientific brand

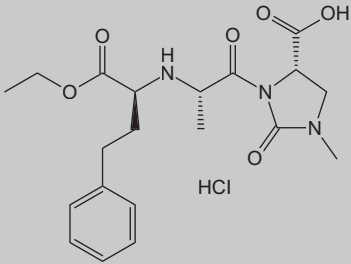
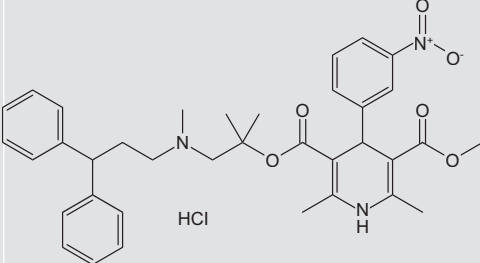
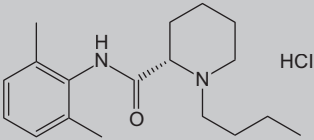
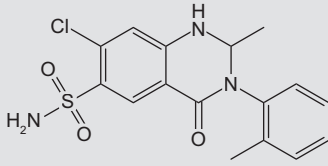
Fisher Scientific Cat. No.	Name	Structure	CAS No.	Pack size	Research Application
AAH36852.MD	Articaine hydrochloride, 98%		23964-57-0	250 mg	Used as a local anaesthetic
AAH36852.03				1 g	
AAH37332.MD	Atipamezole (hydrochloride)		104075-48-1	250 mg	Used as a local anaesthetic α2-adrenoceptor
AAH37332.03				1 g	
AAH37018.MD	Azilsartan		147403-03-0	250 mg	Used in the treatment of hypertension
AAH37018.03				1 g	
AAH37985.MD	Benazepril (hydrochloride)		86541-74-4	250 mg	Used to treat hypertension and congestive heart failure
AAH37985.03				1 g	

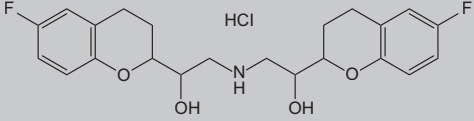
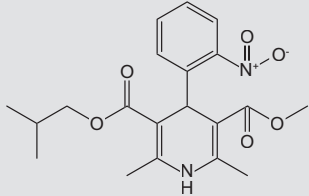
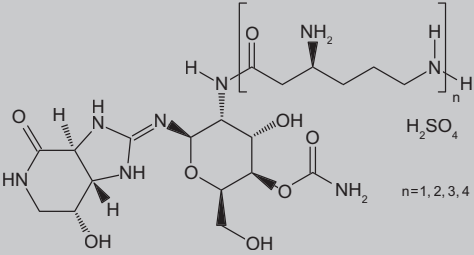
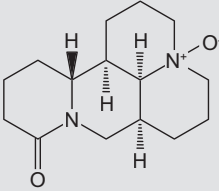


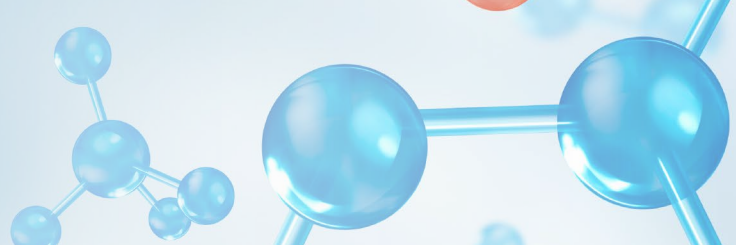
Fisher Scientific Cat. No.	Name	Structure	CAS No.	Pack size	Research Application
AAH37856.MD	Bosentan monohydrate, 98%		157212-55-0	250 mg	Used as a treatment for pulmonary artery hypertension
AAH37856.03				1 g	
AAH37854.MD	Bromocriptine mesylate		22260-51-1	250 mg	An ergoline derivative and dopamine agonist that is used in the treatment of pituitary tumors
AAH37854.03				1 g	
AAH36175.06	Cephalothin (acid), 97%		153-61-7	5 g	Antibiotic with bactericidal activity
AAH36175.14				25 g	
AAH37027.06	Daminozide, 98%		1596-84-5	5 g	Plant growth regulator
AAH37027.14				25 g	

Fisher Scientific Cat. No.	Name	Structure	CAS No.	Pack size	Research Application
AAH36124.MD	Dronedarone hydrochloride, 98%		141625-93-6	250 mg	Used as a treatment for cardiac arrhythmias
AAH36124.03				1 g	
AAH36975.MD	Eprosartan mesylate, 99%		144143-96-4	250 mg	An angiotensin II receptor antagonist used for the treatment of high blood pressure
AAH36975.03				1 g	
AAH37133.MC	Etidocaine hydrochloride, 95%		36637-19-1	100 mg	Articaine hydrochloride, 98%
AAH37120.MD	Fosinopril (sodium), 98%		88889-14-9	250 mg	Used to treat hypertension and congestive heart failure
AAH37120.03				1 g	

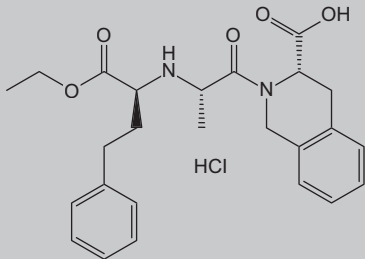
 
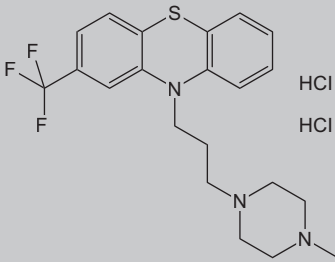
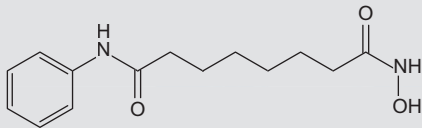


Fisher Scientific Cat. No.	Name	Structure	CAS No.	Pack size	Research Application
AAH37392.MD	Imidapril (hydrochloride), 98%		89396-94-1	250 mg	Used to treat hypertension and congestive heart failure
AAH37392.03				1 g	
AAH36728.MD	Lercanidipine hydrochloride, 98%		132866-11-6	250 mg	Used as a treatment for hypertension
AAH36728.03				1 g	
AAH37643.MD	Levobupivacaine hydrochloride, 98%		27262-48-2	250 mg	Anaesthetic properties
AAH37643.03				1 g	
AAH37934.03	Metolazone, 97%		17560-51-9	1 g	Diuretic used to treat high blood pressure and congestive heart failure
AAH37934.06				5 g	

Fisher Scientific Cat. No.	Name	Structure	CAS No.	Pack size	Research Application
AAH36908.MD	Nebivolol, 98%		152520-56-4	250 mg	Used to treat hypertension
AAH36908.03				1 g	
AAH37972.03	Nisoldipine, 98%		63675-72-9	1 g	Antihypertensive properties
AAH37972.06				5 g	
AAH37154.MC	Nourseothricin sulfate		96736-11-7	100 mg	Antifungal agent
AAH37154.03				1 g	
AAH37340.MD	Oxymatrine, 98%		16837-52-8	250 mg	Has been shown to inhibit apoptosis, tumor and fibrotic tissue development, and inflammation
AAH37340.03				1 g	



Fisher Scientific Cat. No.	Name	Structure	CAS No.	Pack size	Research Application
AAH36603.03	Pizotifen malate		5189-11-7	1 g	Used as a treatment for migraine
AAH36390.06	Pregabalin, 97%		148553-50-8	5 g	Used to treat epilepsy
AAH36390.14				25 g	
AAH36926.MD	Ramipril, 98%		87333-19-5	250 mg	Used to treat hypertension and congestive heart failure
AAH36926.03				1 g	
AAH37974.MD	Ropivacaine, 97%		84057-95-4	250 mg	Anaesthetic properties
AAH37974.03				1 g	
AAH37974.06				5 g	
AAH37451.03	Rosmarinic acid, 97+%		20283-92-5	1 g	Antioxidant properties
AAH37451.06				5 g	

Fisher Scientific Cat. No.	Name	Structure	CAS No.	Pack size	Research Application
AAH37209.MD	Quinapril hydrochloride, 97%		82586-55-8	250 mg	Used to treat hypertension and congestive heart failure
AAH37209.03				1 g	
AAH36265.MD	Tocainide hydrochloride, 98%		71395-14-7	250 mg	Used to treat arrhythmia
AAH36265.03				1 g	
AAH36216.06	Trifluoperazine dihydrochloride, 98%		440-17-5	5 g	Used in treatment of psychosis
AAH36216.09				10 g	
AAH37305.MD	Vorinostat, 98%		149647-78-9	250 mg	Inhibits histone deacetylases
AAH37305.03				1 g	

For more information, visit [fishersci.com/ThermoScientificChemicals](http://fishersci.com/ThermoScientificChemicals) or [fishersci.ca/ThermoScientificChemicals](http://fishersci.ca/ThermoScientificChemicals)

Distributed by Fisher Scientific. Contact us today:

**In the United States**

Order online: [fishersci.com](http://fishersci.com)

Fax an order: 1-800-926-1166

Call customer service: 1-800-766-7000

**In Canada**

Order online: [fishersci.ca](http://fishersci.ca)

Fax an order: 1-800-463-2996

Call customer service: 1-800-234-7437